

## GP8000E

### GP SERIES Portable Generator

#### FEATURES

- **COsense® Technology** – STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **PowerRush™ Advanced Technology** delivers over 30% more starting capacity allowing you to do more with less.\*
- **Electric start** for easy operation (battery included).
- **20ft Generator Cord Included** – Plug in more devices with the multi-outlet generator cord.
- **Generac's OHV engine** with splash lubrication provides a long engine life.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **Large-capacity steel fuel tank** with incorporated fuel gauge provides durability and up to an 15 hour run-time at 25% load (10 hour run-time at 50% load).
- **1 ¼" steel-tube cradle** for added durability and strength.
- **Hour Meter** tracks maintenance intervals.
- **Heavy-duty, never-flat wheels** allow for easy portability.
- **Fold-down handle** for sturdy portability and compact storage.
- **HomeLink™ Manual Transfer Switch compatible** designed to work with HomeLink™ manual transfer switches for safe home backup power.

\* Increases electrical current upon demand; above rated output when starting electric motors.


Model 7675-4 UPC:696471085013  
(49 State)



Photograph may not represent actual content.

AC Rated Output Running Watts 8000  
AC Maximum Output Starting Watts 10000

#### CONTROL PANEL

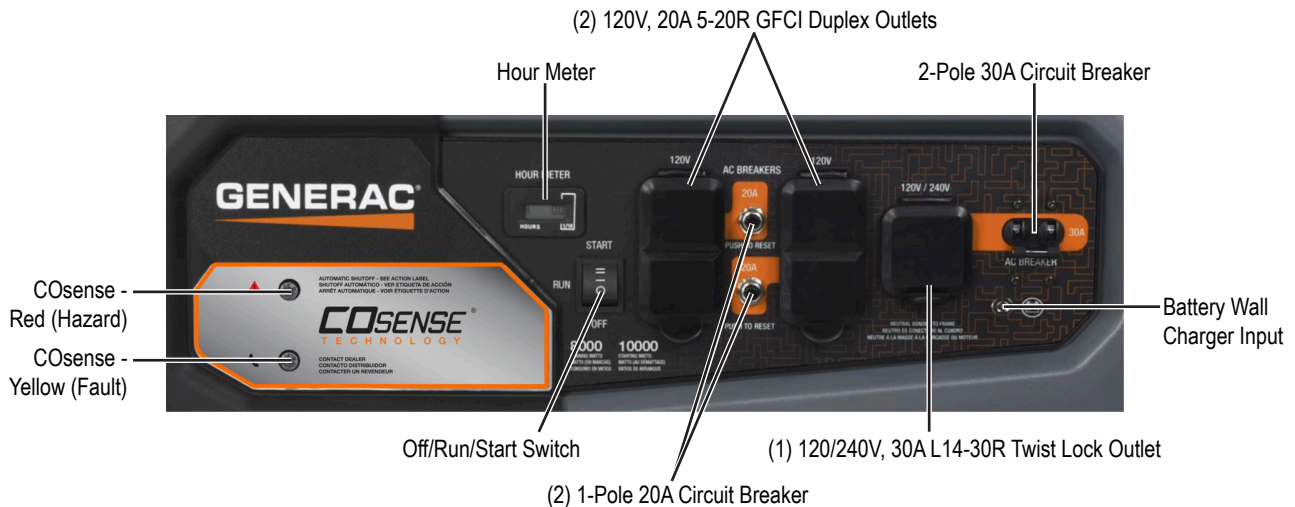

SPECIFICATIONS

Product Series	GP8000E
Model (Configuration)	7675-4 (49-State)
AC Rated Output Running Watts	8000
AC Maximum Output Starting Watts	10000
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	66.6 / 33.3
Engine Displacement	420cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30 / SAE 30
Oil Capacity qt (L)	1.06 (1.0)
Lubrication Method	Splash
Automatic Voltage Regulation (AVR)	Yes
Choke Location	On Engine
Fuel Shut Off	On Fuel Tank
Starting Method	Electric Start / Recoil Pull Start
Battery Included	Yes
Battery Type	Lead Acid (12V DC, 9Ah)

Battery Part No	0G9449
Battery Dimensions	5.94" x 2.56" x 3.70"
Battery Wall Charger Adapter	Included
Low Oil Shutdown	Yes
Neutral Bonded to Ground	Yes
Start Switch Type	Off/Run/Start
Start Switch Location	On Control Panel
Fuel Gauge	Yes
Fuel Tank Capacity Gal (L)	7.9 (29.9)
Run Time at 25% (Hours)	15
Run Time at 50% (Hours)	10
Handle Style	Dual Grip, Single Folding with Lock Pin
Wheel Type	9.5" Never Flat
Generator Cord Included	20ft / 20A Outdoor, Multi-Outlet with Lighted Power Indicator
Warranty- Commercial	2Year Limited
Warranty- Residential	3 Year Limited
Included	20ft generator cord, engine oil, handle & wheel kit, battery & charger, owner's manual

DIMENSIONS AND WEIGHTS

Length in (mm)	27.2 (692)
Width in (mm)	27 (684)
Height in (mm)	26.5 (674)
Extended Length in (mm)	44.9 (1140.9)
Carton Length in (mm)	28.3 (720)
Carton Width in (mm)	21.7 (550)
Carton Height in (mm)	28 (710)
Unit Weight lbs (kg)	198 (90)
Shipping Weight lbs (kg)	220 (99.8)

