

GP7500 DF

GP SERIES Portable Generator

FEATURES

Model 8011-2 UPC:696471103939
(49 State)


- **Dual Fuel** – Runs on gasoline or liquid propane fuel.
- **COsense™ Technology** STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **Electric Start** provides reliable, hassle free startups (battery included).
- **Generac's OHV engine** with splash lube on 420cc engine provides a long engine life.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **Large-capacity steel fuel tank** with incorporated fuel gauge provides durability and up to a 10 hour run-time at 50% load on gasoline and 5 hour run-time at 50% load on LP using a 20 lb tank.
- **Fuel source selector** allows the unit to switch seamlessly between fuel types to prevent unit shutdown.
- **Hour Meter** tracks run-time and maintenance intervals.
- **Heavy-duty never flat wheels** for easy portability.
- **Fold-down locking handle** for sturdy portability and compact storage.
- **HomeLink® manual transfer switch** compatible for safe home backup power.



Photograph may not represent actual content.

AC Rated Output Running Watts 7500 (Gas) / 6800 (LP)
AC Maximum Output Starting Watts 9400 (Gas) / 8500 (LP)

CONTROL PANEL

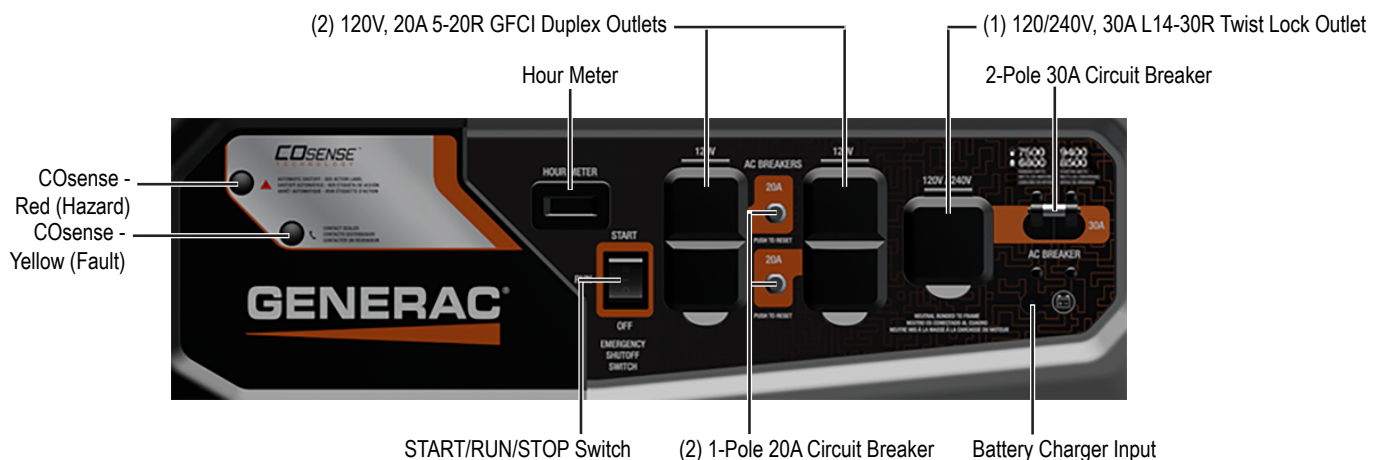

SPECIFICATIONS

Product Series	GP7500E DF
Model (Configuration)	8011-2 (49ST)
AC Rated Output Running Watts	7500 (Gas) / 6800 (LP)
AC Maximum Output Starting Watts	9400 (Gas) / 8500 (LP)
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	62.5 / 31.25
Engine Displacement	420cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30 / SAE 30
Oil Capacity qt (L)	1.06 / 1.0
Lubrication Method	Splash
Automatic Voltage Regulation (AVR)	Yes
Choke Location	On Engine
Fuel Shut Off	On Fuel Tank

Starting Method	Electric Start / Pull Start
Start Switch Type	START/RUN/STOP Switch
Start Switch Location	On Control Panel
Battery Included	Yes
Battery Type	Lead Acid (12V DC, 9Ah)
Battery Part No.	A0003081160
Battery Dimensions	5.3" x 2.95" x 5.26"
Low Oil Level Shutdown	Yes
Neutral Bonded to Ground	Yes
Fuel Gauge	Yes
Fuel Tank Capacity Gal (L)	7.9 (29.9)
Run Time at 50% Rated Load (Hours)	10 (Gas) / 5 (LP)*
Handle Style	Dual Grip, Single Folding with Lock Pin
Wheel Type	9.5" Never Flat
Warranty- Commercial	2 Year Limited
Warranty- Residential	3 Year Limited
Included	Engine oil, oil funnel, handle and wheel kit, owner's manual, charging cable, LP hose, and primary regulator to connect to 20 lb LP tank

* When using a 20 lb. LP tank

DIMENSIONS AND WEIGHTS

Extended Length in (mm)	45.44 (1154.2)
Length in (mm)	28 (710.2)
Width in (mm)	27 (684)
Height in (mm)	27.09 (688)
Carton Length in (mm)	33.46 (850)
Carton Width in (mm)	22.44 (570)
Carton Height in (mm)	26.38 (670)
Unit Weight lbs (kg)	204 (92.5)
Shipping Weight lbs (kg)	234 (106.2)

