

GP5500E

GP5500E Portable Generator

FEATURES


- **10.5-Hour Runtime** when running on gasoline and 50% of power is being used.
- **Easy-to-Use Electric Start** – Rocker switch provides reliable and hassle-free start-ups (Battery included).
- **Fuel-Efficient OHV Engine** – 298cc engine with EFI technology optimizes fuel efficiency and requires less maintenance.
- **Handle & Wheel Kit** – Ergonomic handle and never-flat wheel kit included for portability.
- **1 ¼" steel-tube cradle** for added durability and strength.
- **Covered outlets** provide added protection from the environment and rugged working conditions.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **COsense® Technology** STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **HomeLink® Manual Transfer Switch compatible** designed to work with HomeLink™ manual transfer switches for safe home backup power.

Model G008150-0 UPC: 696471104639 (50-State)



Running / Starting Watts
5500 / 6875

CONTROL PANEL

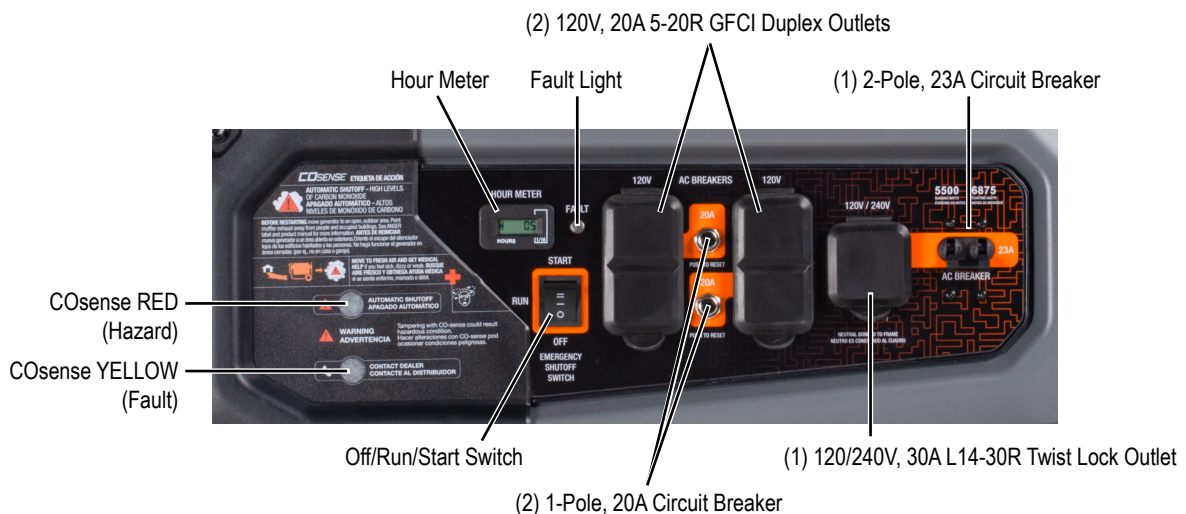

*Made in Vietnam.

SPECIFICATIONS

Product Series	GP5500E
Model Number (Configuration)	8150-0 (50ST)
AC Rated Output Running Watts	5500
AC Maximum Output Starting Watts	6875
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	45.8 / 22.9
Engine Displacement	298cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30 / SAE 30
Oil Capacity qt (L)	0.74 (0.7)
Lubrication Method	Splash
Choke Location	Auto Choke (EFI)
Starting Method	Electric Start / Recoil Pull Start
Start Switch Type	Off/Run/Start
Start Switch Location	On Control Panel

Neutral Bonded to Ground	Yes
Battery Included	Yes
Battery Type	Lead Acid (12V DC, 9Ah)
Battery Part No	A0008504554
Battery Dimensions	5.94" x 2.56" x 3.67"
Low Oil Shutdown	Yes
Fuel Tank Capacity US gal (L)	5.4 (20.5)
Run Time at 25% of Rated Load (Hours)	13.4
Run Time at 50% of Rated Load (Hours)	10.5
Handle Style	Dual Grip, Single Folding with Lock Pin
Wheel Type	9.5" Never Flat
Warranty- Commercial	2 Year Limited
Warranty- Residential	3 Year Limited
Included	Engine oil, oil funnel, handle & wheel kit, battery, owner's manual, spark plug tool

DIMENSIONS AND WEIGHTS

Length in (mm)	27 (686)
Width in (mm)	27 (686)
Height in (mm)	25 (635)
Extended Length in (mm)	44.5 (1130)
Extended Height in (mm)	28 (711)
Carton Length in (mm)	31(765)
Carton Width in (mm)	22 (540)
Carton Height in (mm)	24 (600)
Unit Weight lbs (kg)	163 (74)
Shipping Weight lbs (kg)	181 (82)

