

GP2500i

GP SERIES Residential Inverter Portable Generator

FEATURES

- **COsense® Technology** – STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **Quiet and Neighbor Friendly** fully enclosed design dramatically reduces noise levels.
- **TruePower™ Technology** provides clean, stable power ideal for sensitive electronics, tools and appliances.
- **Compact and Lightweight** makes transportation easy with built-in handle.
- **PowerDial™** - Off, Run, Choke: three operation settings integrated into one simple-to-use dial.
- **LED Indicators** alert you when unit is low on oil, overloaded, or ready-to-use.
- **USB Port** to charge mobile devices.
- **Parallel Ready** to connect any combination of two GP2200i, GP2500i inverter generators or GB1000 or GB2000 Portable Power Stations. (Parallel kit sold separately).
- **Low-oil Level Shutdown** automatically safeguards engine from incurring damage.
- **Covered Outlets** provide added protection from the environment.

Model G0082510 UPC:696471086256
(50 State/CSA)
 Model G0082511 UPC:696471099942
(50 State)
 Model G0082512 UPC:696471103946
(49 State/CSA)




Photograph may not represent actual content.

AC Rated Output Running Watts 2200
 AC Maximum Output Starting Watts 2500



Model 7118-0 UPC:696471072853

CONTROL PANEL

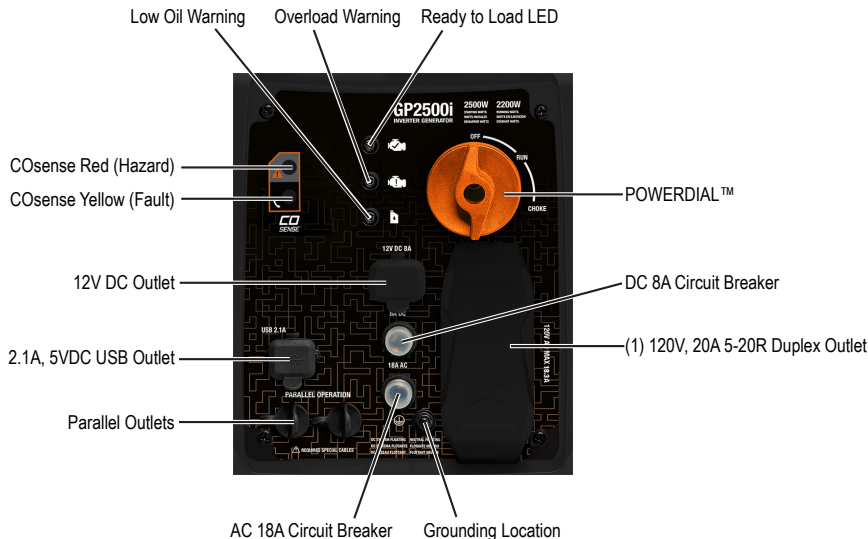

SPECIFICATIONS

Product Series	GP2500i
Model (Configuration)	8251-0 (50-State/CSA) / 8251-1 (50-State) / 8251-2 (49-State/CSA)
AC Rated Output Running Watts	2200
AC Maximum Output Starting Watts	2500
Rated AC Voltage	120 VAC
Rated AC Frequency	60 Hz
Rated 120 VAC Amperage	18.3
Total Harmonic Distortion	3%
Engine Displacement	98cc
Engine Type	OHV
Engine RPM	Variable
Recommended Oil	10W-30
Oil Capacity qt (L)	0.36 (0.35)
Lubrication Method	Splash
Choke Location	On Control Panel
Fuel Shut Off	On Control Panel
Starting Method	Recoil Pull Start

Low Oil Shutdown	Low Level
Floating Neutral	Yes
Start Switch Type	PowerDial™
Start Switch Location	On Control Panel
Fuel Tank Capacity Gal (L)	1.0 (3.75)
Run Time at 25% Rated Load (Hours)	8
Run Time at 50% Rated Load (Hours)	4.5
Warranty- Commercial	2 Year Limited
Warranty- Residential	3 Year Limited

Product Series	Parallel Kit (sold separately)
Model	7118-0
Receptacle Type	(1) L5-30R Twist Lock / (1) TT-30R (RV)
Rated 120 VAC Amperage	28.2 Amp
AC Rated Voltage	120 V
Parallel Kit Warranty- Residential	1 Year
Parallel Kit Warranty- Commercial	1 Year

DIMENSIONS AND WEIGHTS

GP2500i	
Length in (mm)	19.7 (500)
Width in (mm)	11.4 (290)
Height in (mm)	17.9 (455)
Carton Length in (mm)	21.7 (550)
Carton Width in (mm)	12.8 (325)
Carton Height in (mm)	19.3 (490)
Unit Weight lbs (kg)	48 (22)
Shipping Weight lbs (kg)	56 (25.6)

Parallel Kit (sold separately)	
Length in (mm)	9.84 (250)
Width in (mm)	4.33 (110)
Height in (mm)	8.27 (210)
Carton Length in (mm)	11.02 (280)
Carton Width in (mm)	9.37 (238)
Carton Height in (mm)	6.10 (155)
Unit Weight lbs (kg)	3.53 (1.6)
Shipping Weight lbs (kg)	3.8 (1.75)

